

LAMP® Glass Door Hinge Installation Manual


GH-450(Inset) / GH-456N(Overlay) / GH-450G(Inset /Grass frame type)

Thank you for selecting our product. Before installation, please read this manual thoroughly to ensure correct installation. Please keep this manual at hand for future reference.

SPECIFICATIONS


Glass Size	Max. W600 × Max. H1200
Door weight	Max. 15kg/set(GH-450,GH-450G) Max. 6kg/set(GH-456N)
Glass thickness	5, 6, 8 mm

DIMENSIONS

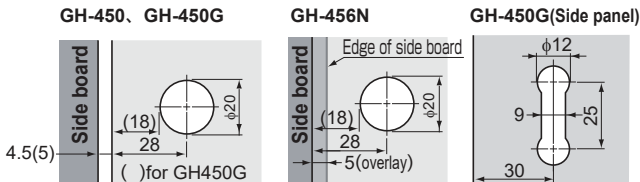

INSTALLATION

The figure shows GH-450.



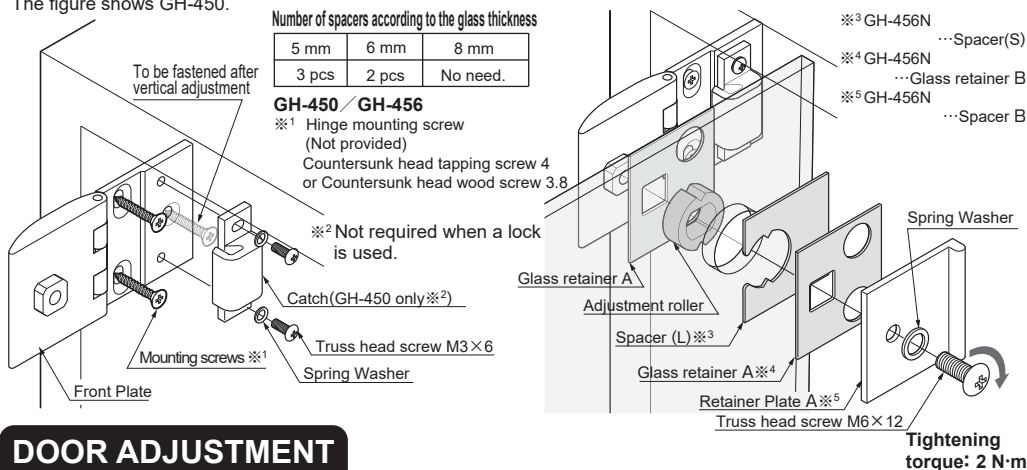


DOOR ADJUSTMENT

Vertical adjustment: (±1 mm)

Horizontal adjustment: (±1.2 mm)

Catch adjustment (GH-450 Only)

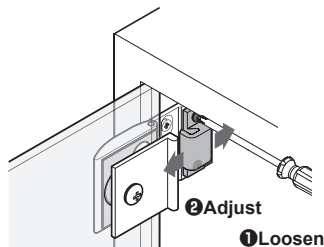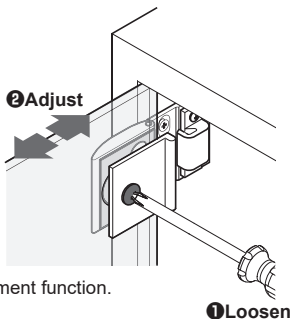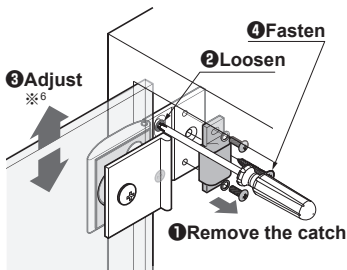

※⁶ GH-450G does not have a vertical adjustment function. The figure shows GH-450 (inset with catch).

After adjustment, be sure to tighten the loosened screws.

Caution
If the catch is set too tight, the catch may be damaged.

SUGATSUNE KOGYO CO., LTD.
Tokyo, JAPAN
Phone: +81 (0)3 3866 2260 E-mail:export@sugatsune.co.jp
SUGATSUNE KOGYO (UK) LTD.
Reading, UK
Phone: +44 118 9272 955 E-mail:sales@sugatsune.co.uk
SUGATSUNE EUROPE GmbH
Düsseldorf, GERMANY
Phone: +49 211 53812900 E-mail:sales@sugatsune.eu
ISO9001(Japan Offices and Sugatsune America) and ISO14001(Chiba Production division and Logistics center), certified.

SUGATSUNE SHANGHAI Co., LTD.
Shanghai, CHINA
Phone: +86 21 3632 1858 E-mail:lamp@sugatsune.com.cn
Guangzhou, CHINA
Phone: +86 20 8639 3554 E-mail:lamp@sugatsune.com.cn
SUGATSUNE KOREA CO., LTD.
Mumbai, INDIA
Phone: +82 32 220 0603 E-mail:sales@sugatsune-korea.co.kr
SUGATSUNE KOGYO INDIA PRIVATE LIMITED
Mumbai, INDIA
Phone: +91 9867299597 E-mail:sales@sugatsune.in

SUGATSUNE AMERICA, INC.
California, USA
Phone: +1 310 329 6373 E-mail:sales@sugatsune.com
Chicago, USA
Phone: +1 630 317 7072 E-mail:sales@sugatsune.com
SUGATSUNE CANADA, INC.
Phone: +1 514 312 5267 E-mail:support@sugatsune.ca